




GE
Lighting

69163 - 38PAR20H/FL25

38PAR20H/FL25

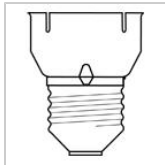

GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR20
Base	Medium Skirt (E26/50x39)
Filament	CC-8
Rated Life	1500.0 hrs
Lamp Enclosure Type (LET)	Covered glass
Bulb Material	Sodalime glass
Primary Application	Indoor Floodlight

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	490.0
Center Beam Candlepower (CBCP)	1450.0
Color Rendering Index (CRI)	100.0
Beam Spread	25.0 °
Nominal Initial Lumens per Watt	12

ELECTRICAL CHARACTERISTICS

Wattage	38.0
Voltage	120.0
Burn Position	Universal

DIMENSIONS

Maximum Overall Length (MOL)	3.1300 in(79.5 mm)
Bulb Diameter (DIA)	2.500 in(63.5 mm)

PRODUCT INFORMATION

Product Code	69163
Description	38PAR20H/FL25
Standard Package	00-Case
Standard Package GTIN	10043168691632
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168691635